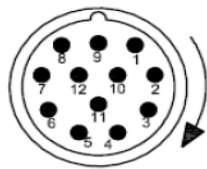
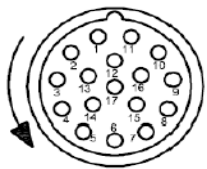
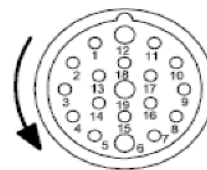
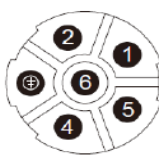



		Partnumbers:	Description	Insert design
M23 Signal		21373300Cxx050	M23 12pole straight male open 5m	
		21373300Cxx100	M23 12pole straight male open 10m	
		21373400Cxx050	M23 12pole angled male open 5m	
		21373400Cxx100	M23 12pole angled male open 10m	
		21373500Cxx050	M23 12pole straight female open 5m	
		21373500Cxx100	M23 12pole straight female open 10m	
		21373600Cxx050	M23 12pole angled female open 5m	
		21373600Cxx100	M23 12pole angled female open 10m	
	xx = 70 for PUR and for 71 PVC cable			
		21373300Fxx050	M23 17pole straight male open 5m	
		21373300Fxx100	M23 17pole straight male open 10m	
		21373400Fxx050	M23 17pole angled male open 5m	
		21373400Fxx100	M23 17pole angled male open 10m	
		21373500Fxx050	M23 17pole straight female open 5m	
		21373500Fxx100	M23 17pole straight female open 10m	
		21373600Fxx050	M23 17pole angled female open 5m	
		21373600Fxx100	M23 17pole angled female open 10m	
	xx = 72 for PUR and for 73 PVC cable			
	21373300Dxx050	M23 19pole straight male open 5m		
	21373300Dxx100	M23 19pole straight male open 10m		
	21373400Dxx050	M23 19pole angled male open 5m		
	21373400Dxx100	M23 19pole angled male open 10m		
	21373500Dxx050	M23 19pole straight female open 5m		
	21373500Dxx100	M23 19pole straight female open 10m		
	21373600Dxx050	M23 19pole angled female open 5m		
	21373600Dxx100	M23 19pole angled female open 10m		
xx = 74 for PUR and for 75 PVC cable				

		Partnumbers:	Description	Insert Design
M23 Power		21373700676050	M23 6pole straight male open 5m PVC	
		21373700676100	M23 6pole straight male open 10m PVC	
		21373800676050	M23 6pole straight female open 5m PVC	
		21373800676100	M23 6pole straight female open 10m PVC	
M23 Hybrid		21373800G78050	M23 4+3+PE straight male open 5m PVC	
		21373800G78100	M23 4+3+PE straight male open 10m PVC	

Other variants on request.